

TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD
 CERTIFICATE ◆ CERTIFICADO ◆ CERTIFIKAT ◆ 證書 ◆ CERTIFICATE ◆ CERTIFICADO ◆ CERTIFIKAT ◆ 證書 ◆ CERTIFICATE




Product Service

CERTIFICATE

No. Z1A 065969 0243 Rev. 00

Holder of Certificate: XP Power Limited
 401 Commonwealth Drive
 Haw Par Technocentre, Lobby B, #02-02
 Singapore 149598
 SINGAPORE

Certification Mark:

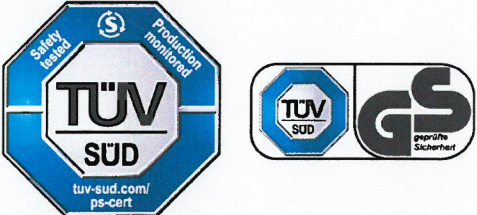

Product: Adaptors (SWITCHING POWER ADAPTOR)

Tested according to: EN 62368-1:2014/A11:2017

The product meets the safety and health requirements of the German Product Safety Act section 20 to 22 ProdSG. The certification marks shown above can be affixed on the product. It is not permitted to alter the certification marks in any way. In addition the certificate holder must not transfer the certificate to third parties. This certificate is valid until the listed date, unless it is cancelled earlier. See also notes overleaf.

Test report no.: 652101916901B

Valid until: 2025-03-24

Date, 2020-05-05 
 (Rickyet Wang)





Product Service

CERTIFICATE

No. Z1A 065969 0243 Rev. 00

Factories: 049020

Model(s): **AFM30USzzC2**
(zz=09-24 indicates rated output voltage 9.0-24.0VDC with step of 1.0VDC)

Brand Name: **XP**



Parameters:

Rated Input: 100-240VAC, 50-60Hz, 1.1A
 Rated Output: See below table for details
 Protection Class: II
 Degree of Protection: IP20

Model	Rated output voltage (VDC)	Rated output current (A)	Max. rated output power (W)
AFM30USzzC2	9.0-12.0	0.10-4.02	48.24
	13.0	0.10-3.70	48.10
	14.0	0.10-3.43	48.02
	15.0	0.10-3.20	48.00
	16.0	0.10-3.00	48.00
	17.0	0.10-2.83	48.11
	18.0	0.10-2.67	48.06
	19.0	0.10-2.53	48.07
	20.0	0.10-2.40	48.00
	21.0	0.10-2.29	48.09
	22.0	0.10-2.19	48.18
	23.0	0.10-2.09	48.07
	24.0	0.10-2.01	48.24

TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD TÜV SÜD
 ZERTIFIKAT ◆ CERTIFICATE ◆ 認證書 ◆ CERTIFICADO ◆ CERTIFICAT

A4 / 07.17