

Certificate



Certificate no.

USA / T 2273577 01

Applicant:

XPiQ, Inc.

260 Hopping Brook Road

Holliston, MA 01746

USA

Manufacturer:

USA - FH/mmw C 2272572 . 01

Test report no.: USA -HJS/mmw C 2272572 . 02 Client Reference: Sean Ross

Tested to: EN 60601-1:1990+A1+A2
IEC 60601-1:1988+A1+A2

Test object: Switching Power Supply (open frame)

Model	Max Power	V1	V2	V3	License Fee-Units
Designation:		Vnom. I _{max}	Vnom. I _{max}	Vnom. I _{max}	
PBM25US05XY	28W	5.1V 5.5A			7
PBM25US12XY	28W	12V 2.3A			
PBM25US15XY	28W	15V 1.9A			
PBM25US24XY	28W	24V 1.2A			
PBM25US28XY	28W	28V 1.0A			
PBM25UD01XY	25W	5,1V 2.5A	+12V 1.5A		
PBM25UD02XY	25W	5,1V 2.5A	+24V 0.8A		
PBM25UT01XY	25W	5,1V 2.5A	+12V 1.5A	-12V 0.2A	

continued on page 2

7

Licensed Test mark:



IEC 60601-1

Signatures

S. Schmitt *J. Raap*

Stephan Schmitt
President

Dipl.-Ing. Raap
QA Certification Officer

Date of Issue
(day/mo/yr)

02/12/2002

Certificate



Certificate no.

USA / T 2273577 02

Applicant:

XPiQ, Inc.

260 Hopping Brook Road

Holliston, MA 01746

USA

Manufacturer:

USA - FH/mmw C 2272572 . 01

Test report no.: USA -HJS/mmw C 2272572 . 02 Client Reference: Sean Ross

Tested to: EN 60601-1:1990+A1+A2
IEC 60601-1:1988+A1+A2

Test object: Switching Power Supply (open frame)


License Fee-Units

Model	Max Power	V1	V2	V3			
Designation:		Vnom.	Imax	Vnom.	Imax	Vnom.	Imax
PBM25UT02XY	25W	5.1V	2.5A	+15V	1.0A	-15V	0.2A
PBM25UT03XY	25W	5.1V	2.5A	+24V	0.8A	-12V	0.2A

(X=A-Z or blank; Y=0-9 or blank)

Rated Voltage: AC 100-240V, 47-63Hz
Rated Current: 0,7A
Protection Class: I

Licensed Test mark:

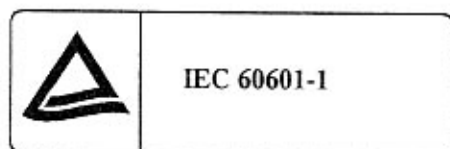

Signatures

S. Schmitt *D. Raap*

Stephan Schmitt
President

Dipl.-Ing. Raap
QA Certification Officer

Date of Issue
(day/mo/yr)
02/12/2002

Certificate



Certificate no.

USA / T 2273579 01

Applicant:

XPiQ, Inc.

260 Hopping Brook Road

Holliston, MA 01746

USA

Manufacturer:

USA - HJS/mmw C 2272574 . 01

Test report no.: USA -HJS/mmw C 2272574 . 02 Client Reference: Sean Ross

Tested to: EN 60601-1:1990+A1+A2
IEC 60601-1:1988+A1+A2

Test object: Switching Power Supply (open frame)

License Fee-Units

Model Design.	Max Power	Vnom. (V1)	Imax (V1)
PBM65US05XY	51W	5.1V	10A
PBM65US12XY	65W	12V	5.5A
PBM65US15XY	65W	15V	4.4A
PBM65US18XY	65W	18V	3.7A
PBM65US24XY	65W	24V	2.8A
PBM65US28XY	65W	28V	2.4A

7

(X=A-Z or blank; Y=0-9 or blank)

Rated Voltage: AC 100-240V, 47-63Hz

Rated Current: 1.6A

Protection Class: I

7

Licensed Test mark:

Signatures

Date of Issue

(day/mo/yr)

02/12/2002



IEC 60601-1

S. Schmitt *A. Raap*

Stephan Schmitt
President

Dipl.-Ing. Raap
QA Certification Officer